


Customer:		<b>Specification</b>		Type: <b>TRD-PS</b>
Symbol	Date	Request No.	Revisions	Client

NOTE :	Spec. No. : <b>04291-T343</b>
--------	----------------------------------


# Specification

Type:  
**TRD-PS**

## 1. Mechanical dimensions (mm)

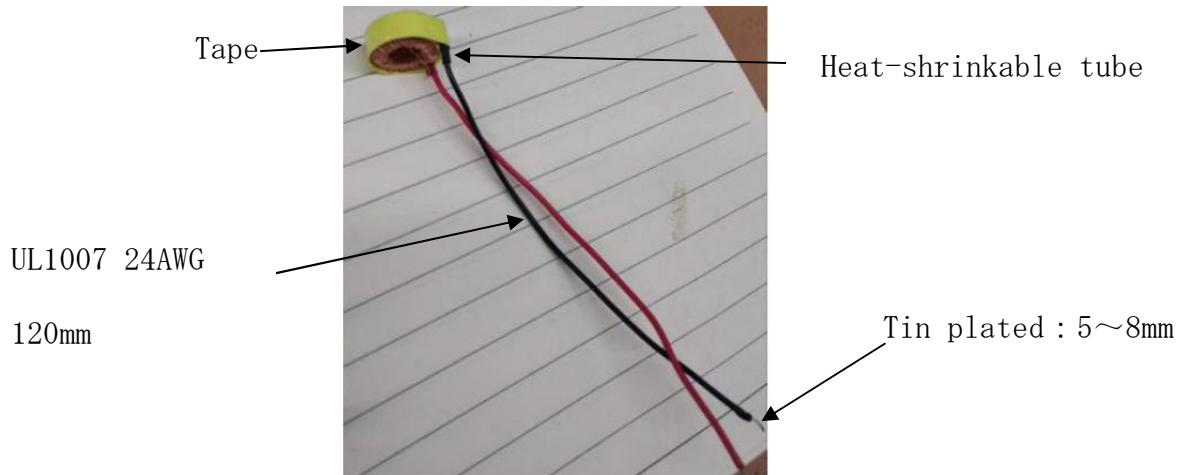

## 2. Schematic

 

**RoHS**

Compliance  
Cd:Max. 0.01wt%  
others: Max. 0.1wt%

## 3. Electrical characteristics (at 25°C unless otherwise specified)

	S-F	Measuring conditions
INDUCTANCE	Min. 30mH	1kHz, 0.25V
D. C. R.	1.65 Ω Max.	

## 4. Note:

\* Coil use  $\phi$  0.23 wire 200Ts.

Approved By	Checked By	Prepared By	SUMIDA P/N		Spec. No. : <b>04291-T343</b>
			Customer P/N		
			First Issue	2020-10-10	
			2/2		